



Nexus® Engineering Data

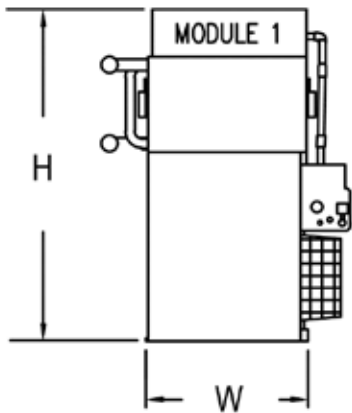

NXF-0403N Models

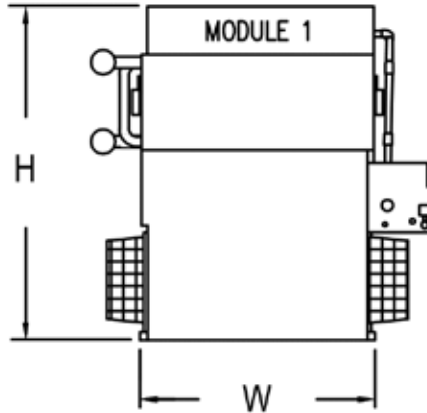


NXF-0603N Models



NOTES:

1. Nominal tons of cooling represents 3 USGPM of water cooled from 95°F to 85°F at a 78°F entering wet-bulb temperature.
2. For structural support, contact your local BAC representative.

Do not use for construction. Refer to factory certified dimensions. This catalog includes data current at the time of publication, which should be reconfirmed at the time of purchase. Up-to-date engineering data, free product selection software, and more can be found at BaltimoreAircoil.com.

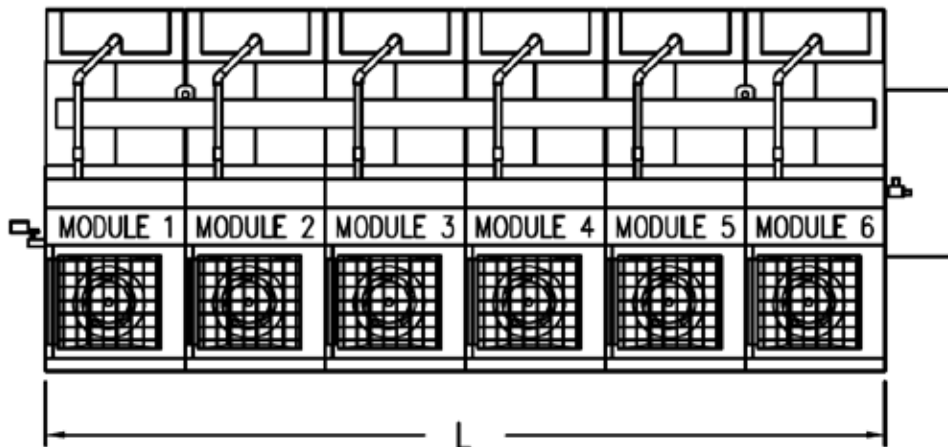

NXF-0x03N-xxxx-x6 Shown

Model Number	Number of Modules	Nominal Tons ⁽¹⁾	Fan Motor HP	Pump Motor HP	Airflow (CFM)	Spray Pump USGPM	Operating Weight (lbs)	Shipping Weight (lbs)	hCore Internal Volume (Gal)	L	W	H
NXF-0403N-CS2TT-H1	1	20	(1) 5	(1) 1/2	8,416	32	2,631	2,242	26	3'-3 1/2"	4'-1 1/2"	8'-6"
NXF-0403N-CS2TT-H2	2	40	(2) 5	(2) 1/2	16,832	64	5,245	4,386	52	6'-7"		
NXF-0403N-CS2TT-H3	3	60	(3) 5	(3) 1/2	25,248	96	7,770	6,482	78	9'-10 1/2"		
NXF-0403N-CS2TT-H4	4	80	(4) 5	(4) 1/2	33,664	128	10,514	8,750	105	13'-2"		
NXF-0403N-CS2TT-H5	5	100	(5) 5	(5) 1/2	42,080	160	13,122	10,882	131	16'-5 1/2"		
NXF-0403N-CS2TT-H6	6	120	(6) 5	(6) 1/2	50,496	192	15,730	13,013	157	19'-9"		
NXF-0603N-CS2TT-J1	1	30	(2) 3.75	(1) 1/2	12,888	50	3,733	3,160	39	3'-3 1/2"	5'-11 1/2"	8'-6"
NXF-0603N-CS2TT-J2	2	60	(4) 3.75	(2) 1/2	25,776	100	7,450	6,223	78	6'-7"		
NXF-0603N-CS2TT-J3	3	90	(6) 3.75	(3) 1/2	38,664	150	11,203	9,363	117	9'-10 1/2"		
NXF-0603N-CS2TT-J4	4	120	(8) 3.75	(4) 1/2	51,552	200	14,923	12,423	156	13'-2"		
NXF-0603N-CS2TT-J5	5	150	(10) 3.75	(5) 1/2	64,440	250	18,718	15,558	195	16'-5 1/2"		
NXF-0603N-CS2TT-J6	6	180	(12) 3.75	(6) 1/2	77,328	300	22,428	18,608	234	19'-9"		